
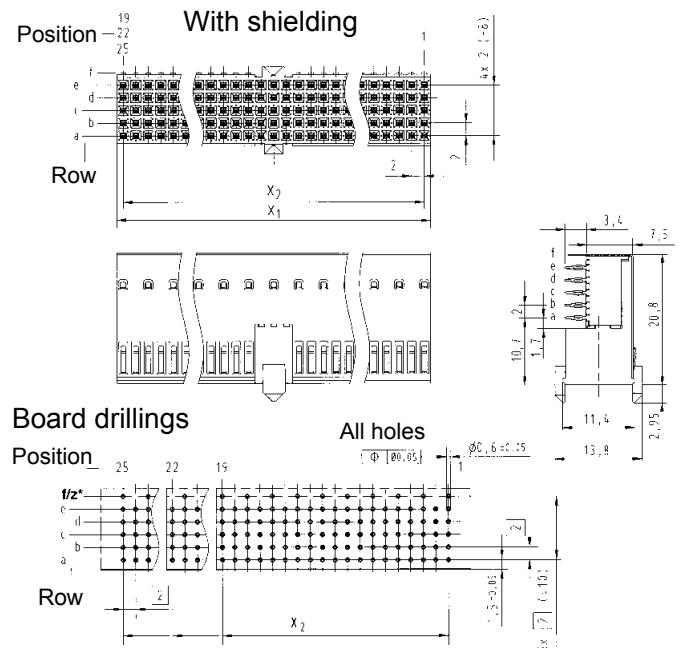


Female connectors, angled

Identification	No. of contacts	Contact length [mm] termination side	Part number
Type AB <sub>19</sub>	95	3.4	17 33 095 1101 <b>17 33 095 2101</b>
Type AB <sub>19</sub> with upper shield CompactPCI, Position RJ3	95	3.4	17 33 095 1102 <b>17 33 095 2102</b>
Lower shield for type AB <sub>19</sub> connectors			17 33 000 4102
Type AB <sub>22</sub>	110	3.4	17 34 110 1101 <b>17 34 110 2101</b>
Type AB <sub>22</sub> with upper shield CompactPCI, Positions RJ2, RJ5	110	3.4	17 34 110 1102 <b>17 34 110 2102</b>
Lower shield for type AB <sub>22</sub> connectors			17 34 000 4102
Type AB <sub>25</sub>	125	3.4	17 35 125 1101 <b>17 35 125 2101</b>
Type AB <sub>25</sub> with upper shield	125	3.4	17 35 125 1102 <b>17 35 125 2102</b>
Lower shield for type AB <sub>25</sub> connectors			17 21 000 4102

Contact positions	X <sub>1</sub>	X <sub>2</sub>
19	37.9	18 x 2 (= 36)
22	43.9	21 x 2 (= 42)
25	49.9	24 x 2 (= 48)

Dimensions [mm]

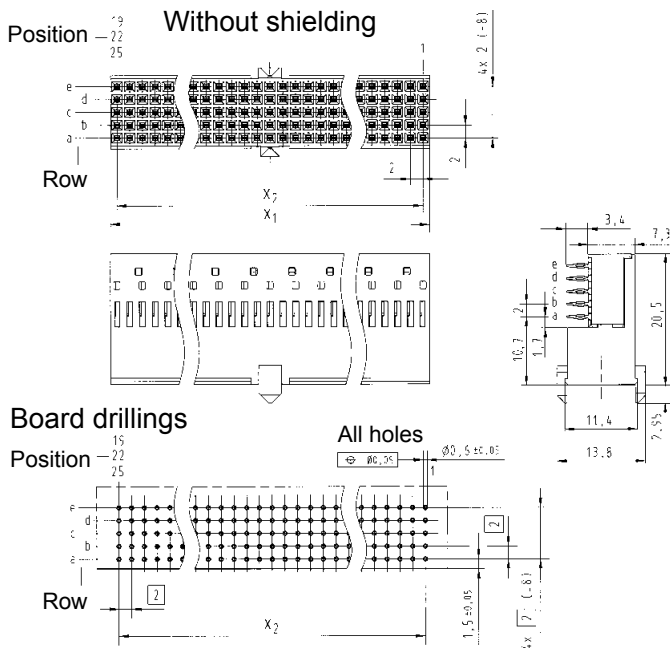

00  
-  
26

Thin print part numbers: performance level 1  
**Bold print part numbers: performance level 2**

\* hole on even contact numbers  
 only needed for lower shielding