


# DIN 41 612 · complementary type 3B

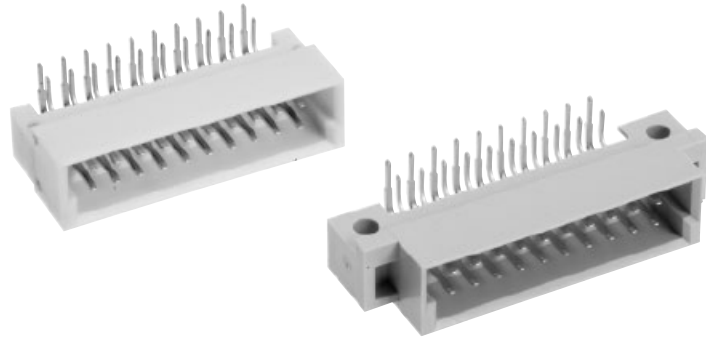

Number of contacts

# 20




Male connectors

Identification	Number of contacts	Contact arrangement	Part No.	Performance levels according to IEC 60 603-2.	
			3	2	1
Male connector with angled solder pins with fixing flange	20		Performance level 3 on request	09 24 120 6921 09 24 320 6921 <sup>b)</sup>	Performance level 1 on request
with fixing flange, SMC	20			09 24 120 6919 <sup>d)</sup>	
without fixing flange	20			09 24 120 6571	
without fixing flange, SMC	20			09 24 120 6579 <sup>d)</sup>	
Male connector with straight solder pins with fixing flange	20		09 24 120 6922		


Dimensions

with fixing flange    without fixing flange

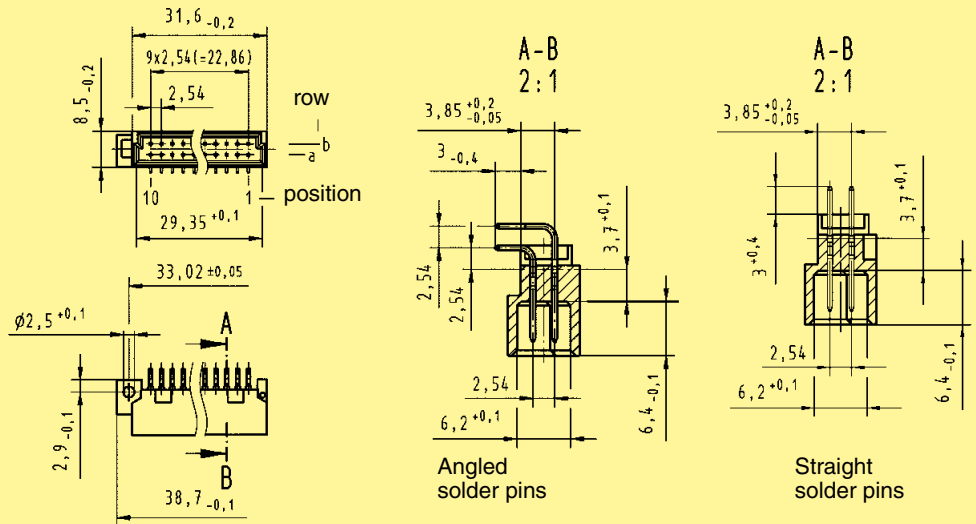


Board drillings

Mounting side

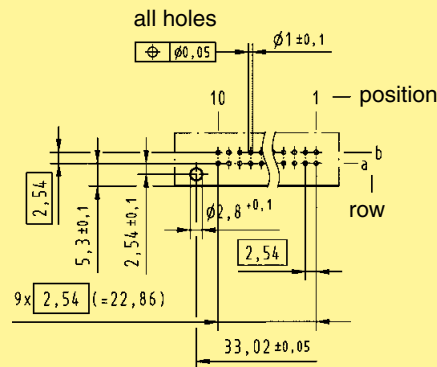

Cross section of solder terminations

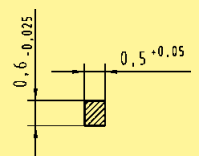

Cross area (A) of contacts row a, b: A = 0.29 - 0.33 mm<sup>2</sup>

Dimensions in mm

Other contact arrangements on request

<sup>b)</sup> Connectors with snap-in clips see chapter 00

<sup>d)</sup> CTI > 400