


DIN 41 612 · complementary type 3C

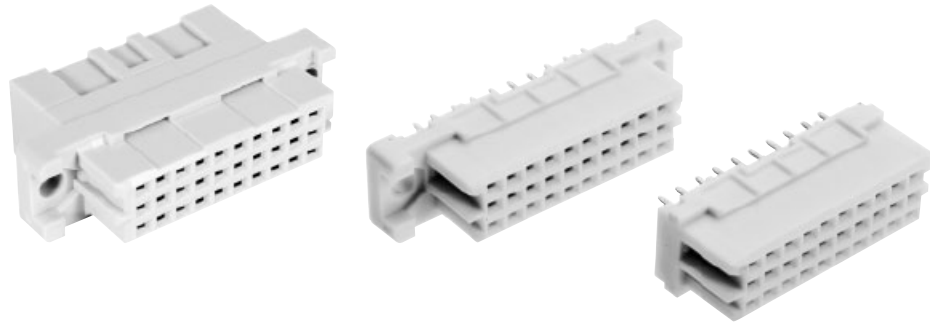

Number of contacts

30, 20



Female connectors

DIN Signal up to 2 A

Identification	Number of contacts	Contact arrangement	Part No.	Performance levels according to IEC 60 603-2.		
			3	2	1	
Female connector with solder pins 2.9 mm						
with fixing flange	30			09 25 230 6824		
	20			09 25 220 6824		
with fixing flange, SMC	30			09 25 230 6841 ^{d)}		
without fixing flange, SMC	30			09 25 230 6414 ^{d)}		
Female connector with solder pins 4.5 mm			Performance level 3 on request		Performance level 1 on request	
with fixing flange	30			09 25 230 6825		
	20			09 25 220 6825		
Female connector with press-in pins 4.5 mm						
with fixing flange	30			09 25 230 6850		
without fixing flange	30			09 25 230 6870		

Identification	Number of contacts	Part No.	Drawing	Dimensions in mm
Female connector for crimp contacts				
Order contacts separately see page 01.27				
Type 3C	30	09 25 030 3214 ^{f)}		
Type 3C	30	09 25 030 3217		
Position marking turned for mating type 3R male				

01
34

^{d)} CTI > 400

^{f)} Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2