


Number of contacts

96, 64

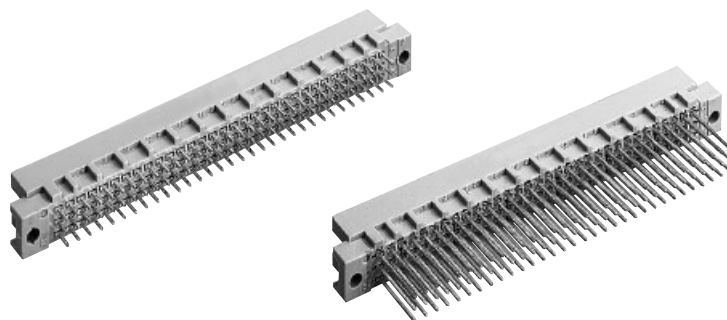

Male connectors

DIN Signal up to 2 A

Identification	Number of contacts	Contact arrangement	Part No.	Performance levels according to IEC 60603-2. Explanation chapter 00		
				3	2	1
Male connector with solder pins 2.5 mm SMC	96		09 73 196 7902	09 73 196 6902 09 73 396 6902 ^{b)} 09 73 696 6902 ^{c)}	09 73 196 2902	
	96			09 73 196 6519 ^{d)}		
	64		09 73 164 7902	09 73 164 6902 09 73 364 6902 ^{b)}	09 73 164 2902 09 73 364 2902 ^{b)}	
Male connector with solder pins 4.0 mm SMC	96		09 73 196 7903	09 73 196 6903 09 73 196 6903 222 ^{f)} 09 73 396 6903 ^{b)} 09 73 196 6953	09 73 196 2903	
	94 + 2 [▲]			09 73 196 6520 ^{d)}		
	96					
Male connector with solder pins 13 mm SMC	96			09 73 196 6577	09 73 196 2577	
	96			09 73 196 6521 ^{d)}		
	64		09 73 164 7903	09 73 164 6903 09 73 364 6903 ^{b)}	09 73 164 2903	
Male connector with wrap posts ¹⁾ 13 mm	96		09 73 196 7907	09 73 196 6907 09 73 696 6947 ^{●c)}	09 73 196 2907	
	64		09 73 164 7907	09 73 164 6907 09 73 164 6947 [●] 09 73 664 6947 ^{●c)}	09 73 164 2907	
Male connector with press-in pins 5.0 mm	96		09 73 196 7904	09 73 196 6904 09 73 696 6904 ^{c)} 09 73 196 6954	09 73 196 2904	
	94 + 2 [▲]					
Male connector with press-in pins 13 mm	96		09 73 196 7974 [●]	09 73 196 6985 ^{w)} 09 73 196 6974 [●] 09 73 196 6995 ^{w)}	Performance level 1 on request	
	94 + 2 [▲]					
Male connector with press-in pins 13 mm	96		09 73 196 7974 [●]	09 73 196 6985 ^{w)} 09 73 196 6974 [●] 09 73 196 6995 ^{w)}	Performance level 1 on request	
	64					09 73 164 6985 ^{w)} 09 73 164 6974 [●]

▲ Male connectors with 2 leading contacts [(0.8 mm) pos. a1 and a32]
 ● Wrap posts for interfacing selectively gold plated (performance level 3)
 f) Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2
 1) To be used only for wire wrap termination

b) Connectors with snap-in clips see chapter 00
 c) Connectors with coding see chapter 00
 d) CTI > 400
 w) Wrap posts not for interfacing, no performance level