


Number of contacts

64

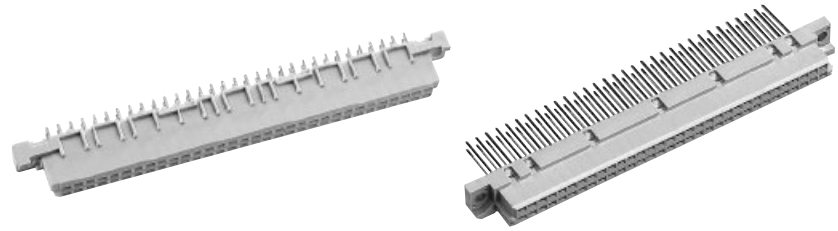

Female connectors

Identification	Number of contacts	Contact arrangement	Part No.	Performance levels according to IEC 60603-2. Explanation chapter 00		
				3	2	1
Female connector with solder pins 2.9 mm	64		Performance level 3 on request	09 02 264 6824 09 02 464 6824 ^{b)} 09 02 764 6824 ^{c)}	09 02 264 2824	
	SMC	64			09 02 264 6841 ^{d)}	
Female connector with solder pins 4.5 mm	64			09 02 264 6825 09 02 264 6825 222 ^{f)} 09 02 464 6825 ^{b)} 09 02 764 6825 ^{c)}	09 02 264 2825	
	SMC	64			09 02 264 6829 ^{d)}	
Female connector with solder pins 13 mm	64			09 02 264 6421		
Female connector with press-in pins 4.5 mm	64			09 02 264 6850 09 02 264 6850 222 ^{f)}	09 02 264 2850	
Female connector with press-in pins without flange 5.3 mm	64			09 02 264 6870		
Female connector with press-in pins 13.2 mm	64			09 02 264 6861 ^{a)}		
Female connector with wrap posts ¹⁾ 13 mm	64			09 02 264 6821		
Female connector with solder lugs 5.2 mm	64		09 02 264 6823			

1) To be used only for wire wrap termination
 a) Wrap posts selectively gold plated (performance level 3)
 b) Connectors with snap-in clips see chapter 00
 c) Connectors with coding see chapter 00

d) CTI > 400
 f) Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2
 Other contact arrangements on request