


DIN 41 612 · complementary type 3Q

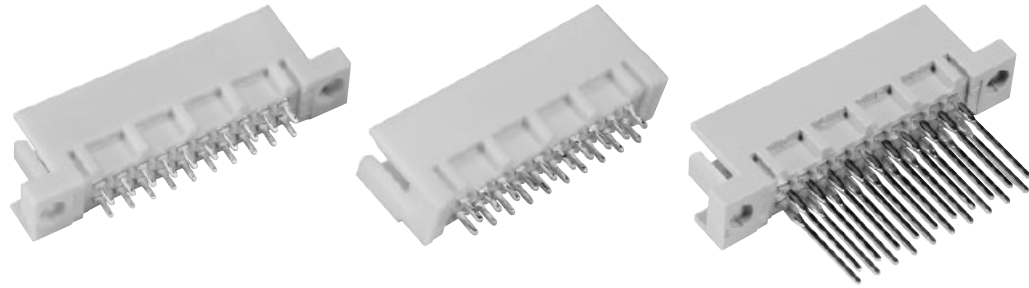

Number of contacts

20



Male connectors

DIN Signal
up to 2 A

Identification	Number of contacts	Contact arrangement	Part No.	Performance levels according to IEC 60603-2. Explanation chapter 00			
				3	2	1	
Male connector with solder pins 2.5 mm			Performance level 3 on request			Performance level 1 on request	
with fixing flange	20						
with fixing flange, SMC	20						09 75 120 6902
without fixing flange	20						09 75 120 6519 ^{d)}
without fixing flange, SMC	20						09 75 120 6592
							09 75 120 6569 ^{d)}
Male connector with solder pins 4.0 mm							
with fixing flange	20						09 75 120 6903
with fixing flange, SMC	20						09 75 120 6520 ^{d)}
without fixing flange	20						09 75 120 6593
without fixing flange, SMC	20						09 75 120 6570 ^{d)}
Male connector with solder pins 13 mm							
with fixing flange	20						09 75 120 6577
with fixing flange, SMC	20						09 75 120 6521 ^{d)}
Male connector with wrap posts¹⁾ 13 mm							
with fixing flange	20						09 75 120 6907
Male connector with press-in pins 5.0 mm							
with fixing flange	20						09 75 120 6904
without fixing flange	20						09 75 120 6504
Male connector with press-in pins 13 mm							
with fixing flange	20		09 75 120 6985 ^{w)} 09 75 120 6974*				
without fixing flange	20		09 75 120 6574*				

01
54

* Wrap posts for interfacing selectively gold plated (performance level 3)

¹⁾ To be used only for wire wrap termination

^{d)} CTI > 400

^{w)} Wrap posts not for interfacing, no performance level