


DIN 41 612 · complementary type 3R

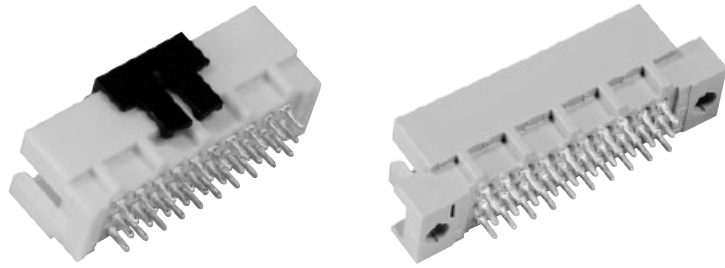

Number of contacts

30, 20



Male connectors

DIN Signal up to 2 A

Identification	Number of contacts	Contact arrangement	Part No.	Performance levels according to IEC 60603-2. Explanation chapter 00		
				3	2	1
Male connector with solder pins 2.5 mm	30		Performance level 3 on request	09 29 130 6902	Performance level 1 on request	
with fixing flange	20			09 29 120 6902		
with fixing flange, SMC	30			09 29 130 6519 ^{d)}		
without fixing flange	30			09 29 130 6592		
without fixing flange, SMC	30			09 29 130 6569 ^{d)}		
Male connector with solder pins 4.0 mm	30			09 29 130 6903		
with fixing flange	20			09 29 120 6903		
with fixing flange, SMC	30			09 29 130 6520 ^{d)}		
without fixing flange	30			09 29 130 6593		
without fixing flange, SMC	30			09 29 130 6570 ^{d)}		
Male connector with solder pins 13 mm	30			09 29 130 6577		
with fixing flange	20			09 29 120 6577		
with fixing flange, SMC	30			09 29 130 6521 ^{d)}		
Male connector with wrap posts ¹⁾ 13 mm	30			09 29 130 6907		
Male connector with press-in pins 5.0 mm	30			09 29 130 6904		
with fixing flange	20		09 29 120 6904			
without fixing flange	30		09 29 130 6504			
Male connector with press-in pins 13 mm	30		09 29 130 6985 ^{w)} 09 29 130 6974*			
with fixing flange	20		09 29 120 6974*			
without fixing flange	30		09 29 130 6574*			

01-58

* Wrap posts for interfacing selectively gold plated (performance level 3)
¹⁾ To be used only for wire wrap termination
^{d)} CTI > 400
^{w)} Wrap posts not for interfacing, no performance level