


Piggyback connectors

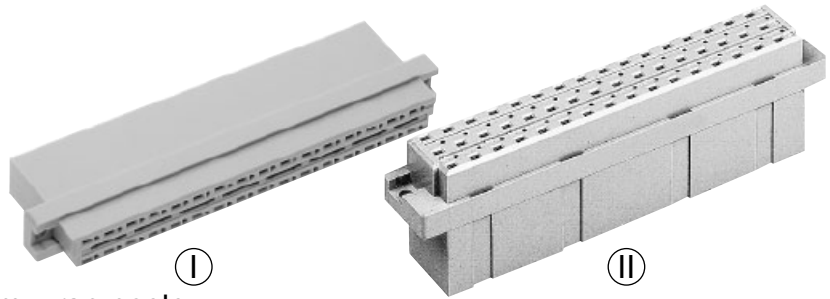

Number of contacts

max. 48



Piggyback connectors for 1 x 1 mm wrap posts

Identification	Number of contacts	Part No.	Drawing	Dimensions in mm
Piggyback connector for crimp contacts Order contacts separately I	16	09 04 016 3201 ¹⁾		
	32	09 04 032 3215 ¹⁾		Reihe row a c Position position
	48	09 05 048 3204 ¹⁾		

DIN Power up to 6 A

¹⁾ Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2