


Number of contacts

48, 32

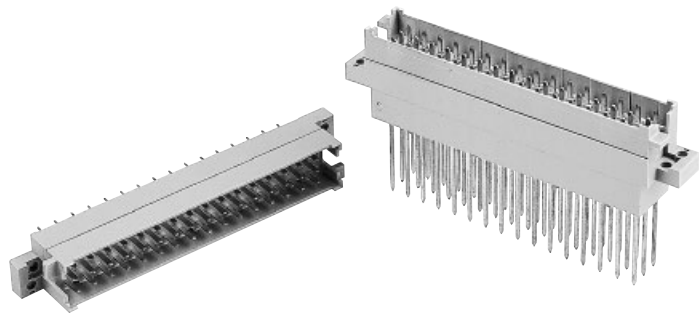

Interface connectors I

Identification	Number of contacts	Contact arrangement	Part No.	Drawing	Dimensions in mm
Interface connector I with solder pins ¹⁾ 0.6 x 0.6 mm	48		Performance level 1* 09 06 048 2905 ^{f)}		
	32		09 06 032 2905 ^{f)}		
	32		09 06 032 2941 ^{f)}		
Board drillings Mounting side					
Interface connector I with wrap posts ¹⁾ 1 x 1 mm	without nut		Performance level 1* 09 06 048 2903 ^{f)}		
	with nut		09 06 048 2963 ^{f)}		
	without nut		09 06 032 2903 ^{f)}		
Panel cut out					

DIN Power up to 6 A

03
-
28

* Acc. to IEC 60 603-2, performance level 2 on request
¹⁾ With shroud coding, see also chapter 00
^{f)} Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2