


Number of contacts

48

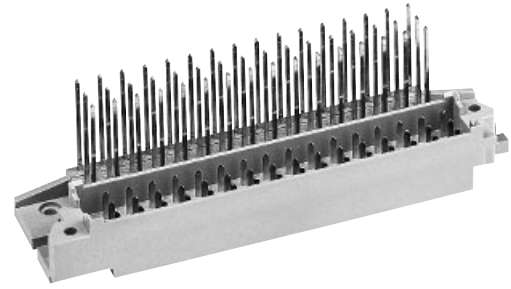

Interface connector U

Identification	Number of contacts	Part No.	Drawing	Dimensions in mm
Interface connector U with wrap posts 1 x 1 mm	48	Performance level 1 acc. to IEC 60 603-2 09 06 048 2981 <sup>1)</sup>	<p>Technical drawing showing side and top views of the connector. Dimensions include: 3±0.2, 2, 22, 6.8, 15.2, 15.2, 14.8, 12.5, 15×5.08=76.20, 2×5.08=10.16, 3.2±0.1, 31.9, 17.2, 101±0.2, 106.5±0.2, M2.5, 0.3, 94, 90, 81.7, 0.3.</p>	<p>Technical drawing showing side and top views of the connector. Dimensions include: 94, 90, 81.7, 0.3, 5.08, M 3 x 8 DIN EN ISO 1207, 17.23, 10.16, 81.7, 90±0.1, 5.63, 5.08, 32, 32, 32, 32, 14.69, 2.4, M 2.5 x 6 DIN EN ISO 1207, A-B.</p>
Mounting example				

DIN Power up to 6 A

<sup>1)</sup> Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2