


Number of contacts

**max. 24**

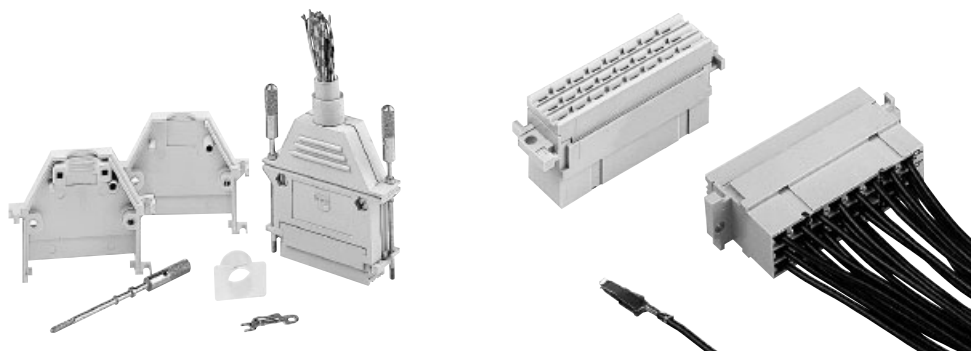

Female connectors

DIN Power  
up to 6 A

Identification	Number of contacts	Part No.	Drawing	Dimensions in mm
<p>Female connector for crimp contacts</p> <p>Order contacts separately see page 03.31</p>	24	09 26 024 3201 <sup>1)</sup>		
<p>Shell housing A with integrated fixing screws</p> <p>Supplied with:                      Shell 2x                      Locking screw 2x                      Screw M3x10 2x                      Nut M3 2x                      Screw BZ 2.9x9.5 2x                      Cable clamp 1x                      Tension relief 1x</p>		09 26 024 0401 <sup>1)</sup>		
<p>Open hood</p> <p>Supplied with:                      Open hood 1x                      Locking screw 2x                      Screw BZ 2.2x9.5 2x                      Cable tie 1x</p>		09 26 000 9901 <sup>1)</sup>		

<sup>1)</sup> Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2