


Shell housing A for type F

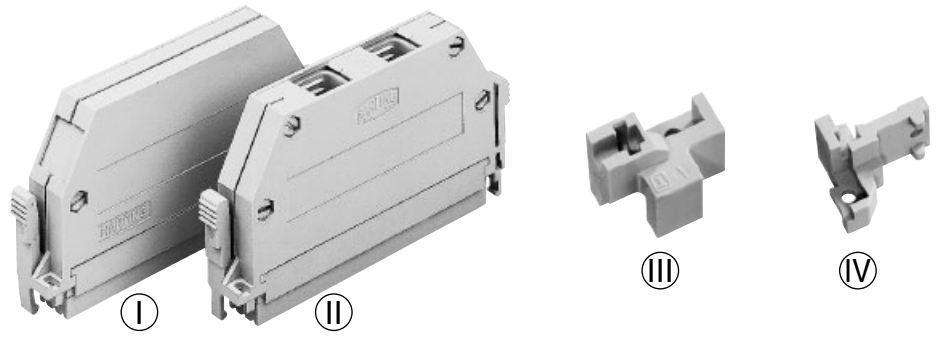

Identification Part No. Drawing Dimensions in mm

<p>Shell housing A</p> <p>Side entry I</p>	<p>15 mm 09 06 048 0501^{f)}</p>		
<p>Top entry II</p>	<p>15 mm 09 06 048 0402^{f)}</p>		
<p>Cable clamp incl. screw</p>	<p>09 06 001 9986</p>	<p>1 x ④ + 2 x ⑤ on page 20.10</p>	
<p>Fixing brackets A for male connectors for 19" racks according to DIN EN 60 297, part 3-101</p> <p>Multiple fixing III</p>	<p>left 09 06 000 9901^{f)}</p> <p>right 09 06 000 9902^{f)}</p>		<p>1) nut and screw not supplied with bracket</p>
<p>Single fixing IV</p>	<p>left 09 06 000 9905^{f)}</p> <p>right 09 06 000 9906^{f)}</p>		

^{f)} Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2