


Shell housing B

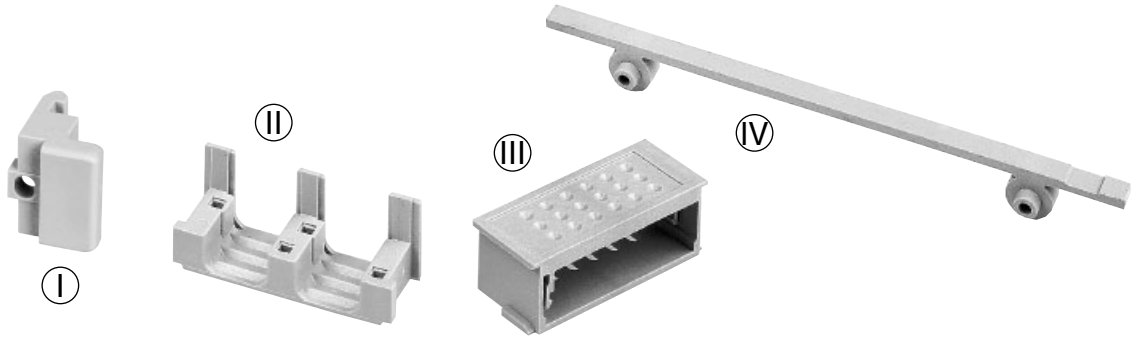

Accessories

| Identification | Part No. | Drawing | Dimensions in mm |
|--|------------------------------|---|------------------|
| <p>Fixing brackets B for female connectors for 19" racks according to DIN EN 60297, part 3-101</p> <p>Multiple fixing I</p> <p>¹⁾ Order 2 pieces for one female connector</p> | 09 06 000 9933 ¹⁾ | <p>M 2.5 x 8 DIN EN ISO 1207²⁾</p> <p>Female connector type F</p> <p>2x 09 06 000 9912</p> | |
| <p>Round cable insert 2 x ø 10</p> <p>for shell housings B 09 06 048 0503 09 06 048 0504</p> <p>Supplied with: Round cable insert 1x Blinding piece 1x</p> | 09 06 000 9914 | <p>max ø 10 min ø 7</p> <p>10 12</p> | |
| <p>Round cable insert 2 x ø 12.5</p> <p>II</p> <p>for shell housing B 09 06 048 0505</p> <p>Supplied with: Round cable insert 1x Blinding piece 1x</p> | 09 06 000 9915 | <p>max ø 12.5 min ø 7</p> <p>14.5 12</p> | |
| <p>Insert for LED</p> <p>III</p> <p>for shell housing B 09 06 048 0505</p> | 09 06 000 9917 | <p>3.5 L₀</p> <p>pcb 35.5 x 17 x 1.5</p> <p>508 162</p> <p>3.2 a 2.5</p> <p>A-B C-D</p> | |
| <p>Protection strip</p> <p>IV</p> <p>Used with shell housings type B for front side access 09 06 048 0504 09 06 048 0505</p> | 09 06 000 9929 | <p>128.5</p> <p>88.9±0.1</p> <p>5</p> <p>09 06 000 9909 09 06 000 9910</p> <p>Male connector type F</p> <p>20</p> | |