


Shell housing D 20 for types F, H and MH

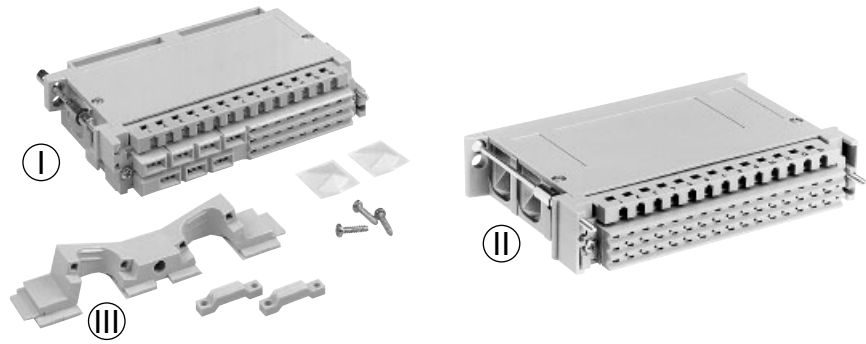

Shell housings

20
-
22

| Identification | Part No. | Drawing | Dimensions in mm |
|---|-------------------------|---------|------------------|
| Shell housing D 20/2 Two side cable entries I | 20 mm 09 06 048 0521 | | |
| Shell housing D 20/4 Four side cable entries II Supplied with: Shell 1x Cover 1x Locking screw 2x (09 06 000 9920) Locking washer 2.3 2x Screw BZ 2.2x9.5 12x Blinding piece 3x Cable clamp 2x | 20 mm 09 06 048 0522 | | |
| Inserts e. g. for LED* for 55 mm height | 09 06 000 9986 | | |
| for 60 mm height | 09 06 000 9987 | | |
| Round cable insert* 2 x Ø 11 III | 09 06 000 9988 | | |
| Flat cable insert* | 09 06 000 9989 | | |

* Fits D 20/2
 Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2