


Shell housing D 20 metallised for types F, H and MH

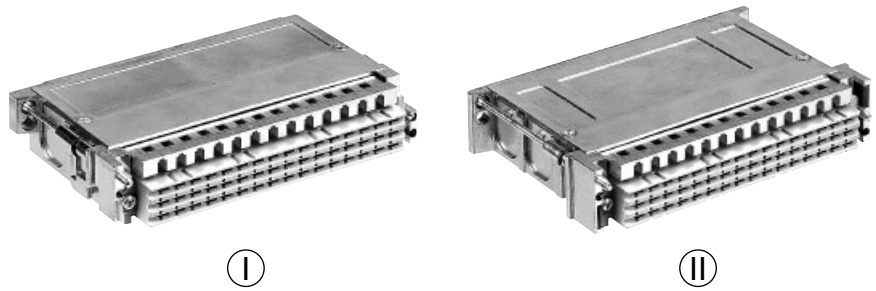

(I)

(II)

Identification	Part No.	Drawing	Dimensions in mm
<p>Shell housing D 20/2 metallised with two side cable entries</p> <p>(I)</p> <p>Supplied with: see page 20.20</p>	<p>20 mm 09 06 948 0521</p>	<p>Order inserts separately</p>	
<p>Shell housing D 20/4 metallised with four side cable entries</p> <p>(II)</p> <p>Supplied with: Shell 1x Cover 1x Locking screw 2x (09 06 000 9920) Locking washer 2.3 2x Screw BZ 2.2x7.5 12x Blinding piece 3x Cable clamp 2x</p>	<p>20 mm 09 06 948 0522</p>		
<p>Metallised insert e. g. for LED*</p> <p>for 55 mm height</p>	<p>09 06 900 9986</p>		
<p>for 60 mm height</p>	<p>09 06 900 9987</p>		
<p>Metallised round cable insert* 2 x ø 11</p>	<p>09 06 900 9988</p>		

Shell housings

20
27

* Fits D 20/2 metallised
Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2