


Shell housing D 20 metal HF for types F, H and MH

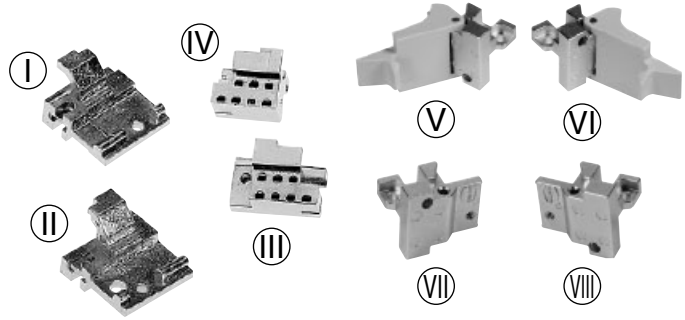

| Identification | Part No. | Drawing | Dimensions in mm |
|--|---|---------|------------------|
| <p>Fixing brackets B metallised for male connectors for 19" racks according to DIN EN 60 297, part 3-101</p> <p>Single fixing (I) with nut M 2.5 DIN EN ISO 4 036 (II)</p> | <p>left 20 mm 09 06 901 9924¹⁾</p> <p>right 20 mm 09 06 901 9925¹⁾</p> | | |
| <p>Multiple fixing with coding at fixing bracket with nut M 2.5 DIN 562 (III)</p> <p>(IV)</p> | <p>left 20 mm 09 06 900 9997¹⁾</p> <p>right 15 mm 09 06 900 9996¹⁾</p> | | |
| <p>Fixing brackets B metal for male connectors for 19" racks according to DIN EN 60 297, part 3-101</p> <p>Single fixing with ejector handle (V)</p> <p>(VI)</p> <p>without ejector handle (VII)</p> <p>(VIII)</p> | <p>left 09 06 800 9946</p> <p>right 09 06 800 9948</p> <p>left 09 06 800 9966</p> <p>right 09 06 800 9968</p> | | |

Shell housings

¹⁾ Railway classification NFF 16-101, Smoke index: F1, Flammability class: I2