


### Automated crimping machine type BK

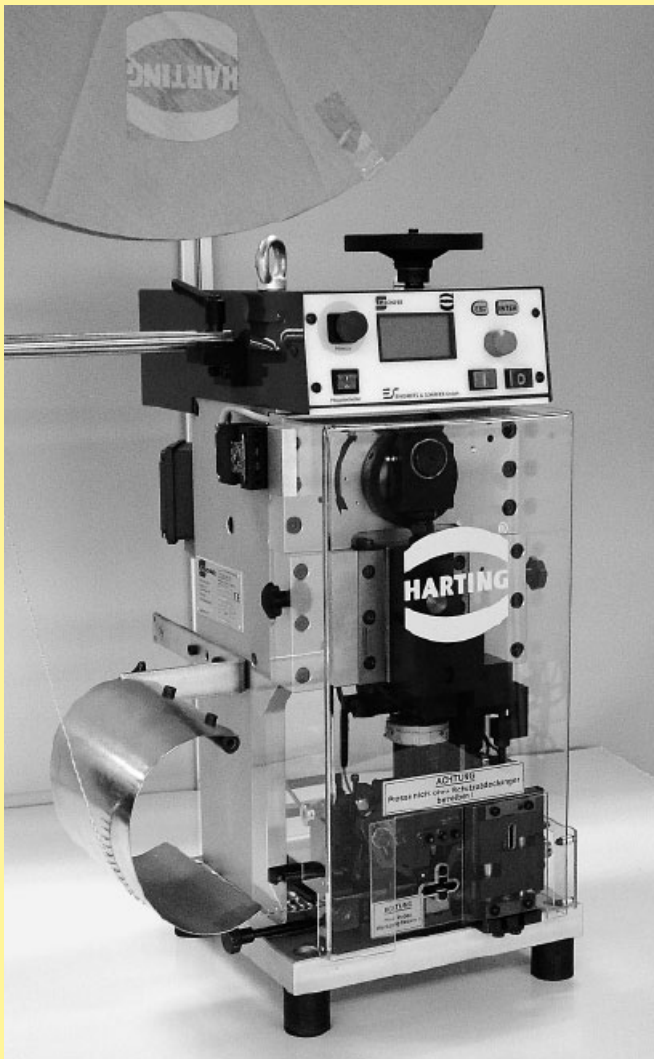

#### Main characteristics

- Smooth run through electronic brakes
- Hand wheel for manual adjustments
- Maintenance friendly through needle bearing rail
- Simple handling by quick change tool and stripper

**Part No. 09 98 000 5000**

#### Technical Characteristics

##### Dimensions

Height 690 mm  
(1400 mm with a contact reel)

Width 350 mm

Depth 370 mm

Total weight 72 kg

Power supply 230 V, 50/60 Hz, 2.5 A

Consumption 0.75 kW

Motor speed 440 - 2000 rpm

Cable length 2 m incl. plug

Control SPS

Work cycle trigger Sensor

Work cycle 0.35 s for stripping and crimping

Illumination Integrated tool light

Stroke counter Daywise and fixed

Crimp force monitor BB07i

Crimping tool Quick change tool

Adjustable process parameters  
 Crimping height on wire  
 Crimping height on insulation  
 Depth of insulation stripping  
 Length of insulation stripping  
 Wire retainer position  
 Wire position in the crimp contact  
 Band thrust