

Number of contacts

14-68



Male connectors for IDC discrete wire, straight

Identification	No. of contacts	Part No.
Male connectors with insulation displacement termination for discrete wire AWG 28/30 Insulation diameter (mm) Ø = 0.50-0.65 Ø = 0.50-0.75 Ø = 0.75-0.90		Male connector
	14	60 13 014 52 . . .
	20	60 13 020 52 . . .
	26	60 13 026 52 . . .
	36	60 13 036 52 . . .
	50	60 13 050 52 . . .
	68	60 13 068 52 . . .


Available sizes

	Part No.	Ø	14	20	26	36	50	68
Male	60 13 . . . 5200	0.50-0.65		●			●	●
	60 13 . . . 5205	0.50-0.75	●		●	●		
	60 13 . . . 5215	0.75-0.90	●		●	●		





● = Available sizes

Dimensions for male connectors

20 / 50 / 68 poles

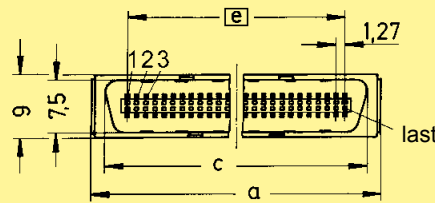


	a	c	e
20	21.24	17.55	11.43
50	40.29	36.60	30.48
68	51.72	48.03	41.91

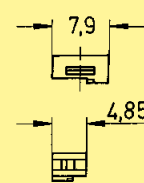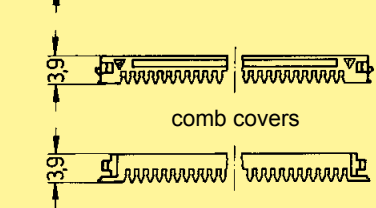  



14 / 26 / 36 poles



A manual for the *har-mik*® connector and cable assembly is available in our online catalogue *HARKIS*® or on demand at your local HARTING representative.

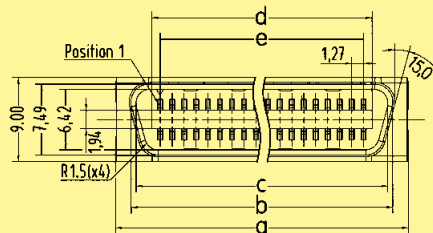

	a	b	c	d	e
14	17.10	13.84	12.78	9.42	7.62
26	24.95	21.46	20.40	17.00	15.24
36	31.35	27.81	26.75	23.39	21.59

 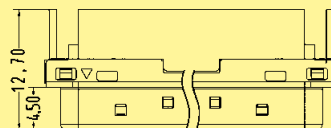

Dimensions in mm