


Top or side entry hoods


Identification No. of contacts Part No. Drawing Dimensions in mm

Plastic hood with internal screen


14	60 13 014 0153 351 ¹⁾
20	60 13 020 0153 ²⁾
26	60 13 026 0153 351 ¹⁾
36	60 13 036 0153 351 ¹⁾
50	60 13 050 0153 ²⁾
68	60 13 068 0153 ²⁾

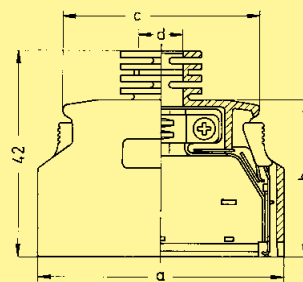


	a	b	c	d
20	29.65	34.50	19.95	6.80
50	48.70	32.00	39.00	8.70
68	60.13	32.00	50.43	9.10

 

20 / 50 / 68 poles

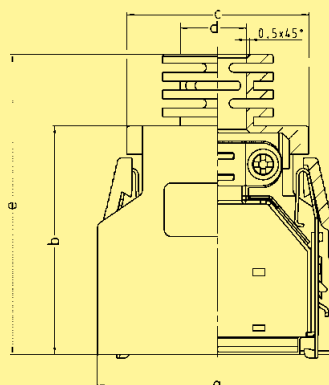

	a	b	c	d	e
14	26.00	36.00	21.00	7.20	42.50
26	33.70	32.00	25.50	8.00	42.00
36	40.05	32.00	31.80	9.20	42.00

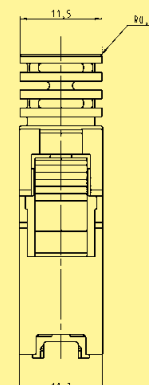


14 / 26 / 36 poles

Metal hood


Cable side entry

Only compatible with IDC connector
60 13 026 5200

26	60 13 026 0555
----	----------------

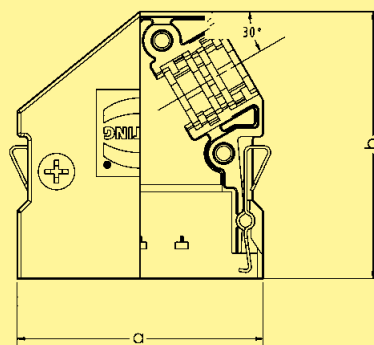

	Shell dimensions		Cable dimensions	
	a	b	min.	max.
26	33.8	36.8	6.5	8.5

 

¹⁾ Temperature range: - 55 °C ... + 85 °C
²⁾ Temperature range: - 55 °C ... + 60 °C