
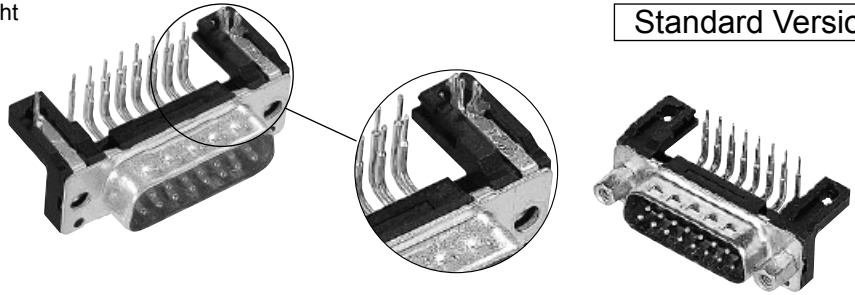


Number of contacts

Mounting height

Standard Versions

9-37
50

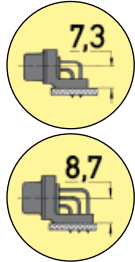

Turned solder pins, angled with/without snap-in-clips and grounding board locks

Identification

Drawing


Dimensions in mm

Male connector

With snap-in clips and grounding board locks

Without snap-in clips and grounding board locks

Board drillings

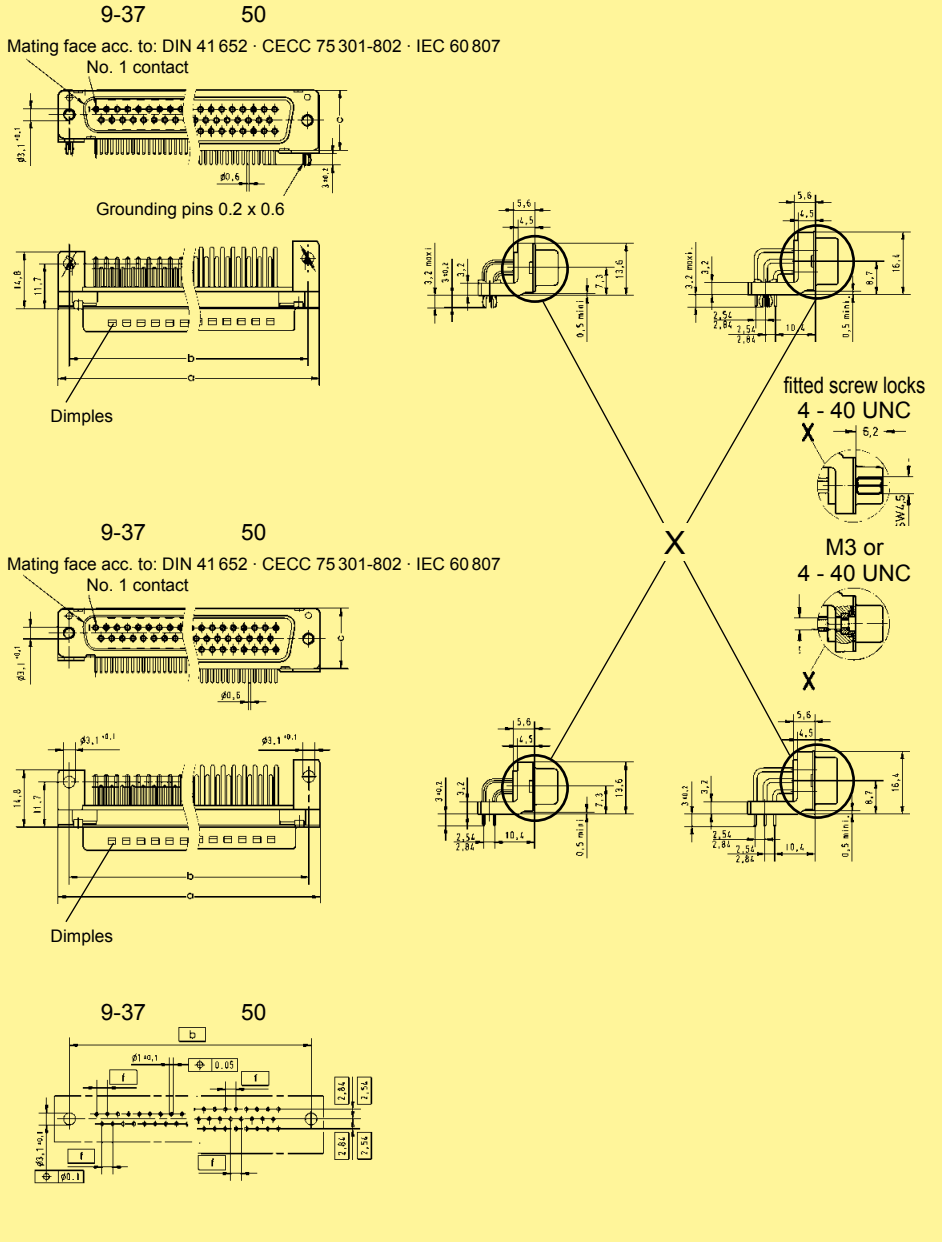

	a	b±0.1	c	f
9	30.90	25.00	12.90	2.74
15	39.20	33.30	12.90	2.74
25	53.10	47.00	12.90	2.76
37	69.40	63.50	12.90	2.76
50	67.00	61.10	15.70	2.76