


U.S. Footprint

Number of contacts

Mounting height

9-37

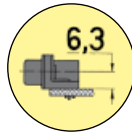

Stamped solder pins, angled with snap-in-clips and grounding board locks

D-Sub - S

Identification	No. of contacts	Part No.	
<b>Performance levels</b> Explanations see page 02.02 Other performance levels on request		Performance level <b>3</b>	
		S4 <sup>1)</sup>	
<b>Male connector</b> metal shell with dimples		2.84 mm pitch	
	9	09 68 163 781	09 68 163 581
	15	09 68 263 781	09 68 263 581
	25	09 68 363 781	09 68 363 581
	37	09 68 463 781	09 68 463 581
<b>Female connector</b> metal shell		2.84 mm pitch	
	9	09 68 153 761	09 68 153 561
	15	09 68 253 761	09 68 253 561
	25	09 68 353 761	09 68 353 561
	37	09 68 453 761	09 68 453 561
Please insert digit for flange thread or fitted female screw locks			
	M3 ▶ <sup>12)</sup>		
	4-40 UNC ▶ 2		
	fitted screw locks 4-40 UNC ▶ 3		

<sup>1)</sup> S4 = 0.76 µm (30 µinch) Au or PdNi equivalent

<sup>2)</sup> Not normally kept in stock