


Stamped crimp contacts

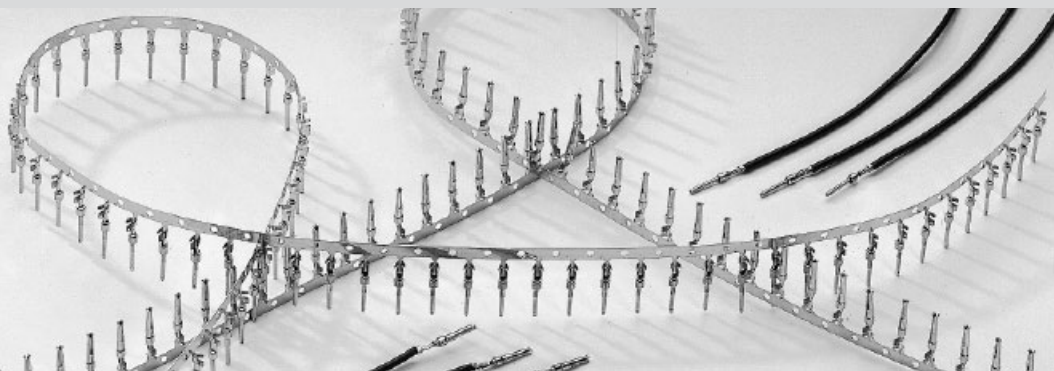

D-Sub - S

Identification	Wire gauge (mm ²)	Part No.		
Performance levels Explanations see page 02.24 Other performance levels on request		stamped male contacts		
		Performance level 3	Performance level 2	Performance level 1
Individual contacts 500 pieces/reel Unrolling left 10 000 pieces/reel Unrolling left Unrolling left reversed Unrolling right reversed	AWG 28-24 0.09-0.25 stranded	09 67 000 7177 ¹⁾ 09 67 000 7167 09 67 000 7157 09 67 000 7147 09 67 000 7137	09 67 000 7178 ¹⁾ 09 67 000 7168 09 67 000 7158 09 67 000 7148 09 67 000 7138	09 67 000 7176 ¹⁾ 09 67 000 7166 09 67 000 7156 09 67 000 7146 09 67 000 7136
Individual contacts 500 pieces/reel Unrolling left 10 000 pieces/reel Unrolling left Unrolling left reversed Unrolling right reversed	AWG 24-20 0.25-0.56 stranded	09 67 000 8177 ¹⁾ 09 67 000 8167 09 67 000 8157 09 67 000 8147 09 67 000 8137	09 67 000 8178 ¹⁾ 09 67 000 8168 09 67 000 8158 09 67 000 8148 09 67 000 8138	09 67 000 8176 ¹⁾ 09 67 000 8166 09 67 000 8156 09 67 000 8146 09 67 000 8136
Unrolling direction		<p style="text-align: center;">for HARTING tools</p>		

¹⁾ Minimum order 500 pieces or multiples of 500
 Insertion and removal tool see chapter 31
 Contact dimensions see page 02.29