


Number of contacts

**9-37**

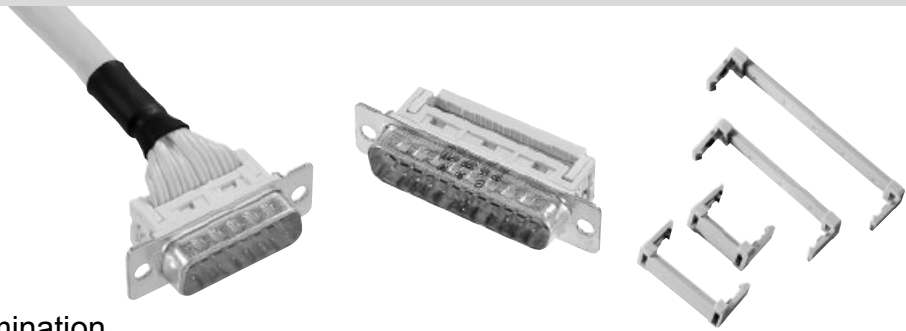

Insulation displacement termination

D-Sub - S

Identification	No. of contacts	Part No.	
<b>Performance levels</b> Explanations see page 02.24 Other performance levels on request		Performance level <b>3</b>	
		Performance level <b>2</b>	
<b>Male connector<sup>2)</sup></b> pitch 1.27 mm metal shell with dimples	9 15 25 37	09 66 128 770 09 66 228 770 09 66 328 770 09 66 428 770	09 66 128 670 09 66 228 670 09 66 328 670 09 66 428 670
<b>Female connector<sup>2)</sup></b> pitch 1.27 mm metal shell	9 15 25 37	09 66 118 750 09 66 218 750 09 66 318 750 09 66 418 750	09 66 118 650 09 66 218 650 09 66 318 650 09 66 418 650
Please insert digit for flange thread			
ø 3.1 mm hole ▶ 0 M3 ▶ 1 <sup>1)</sup> 4-40 UNC ▶ 2			
<b>Strain relief clamp</b> plastic for male and female connector	9 15 25 37	09 66 108 0001 09 66 208 0001 09 66 308 0001 09 66 408 0001	09 66 108 0001 09 66 208 0001 09 66 308 0001 09 66 408 0001

<sup>1)</sup> Not normally kept in stock  
<sup>2)</sup> Not released for halogen free flat cables