


Crimp contacts for high density connectors

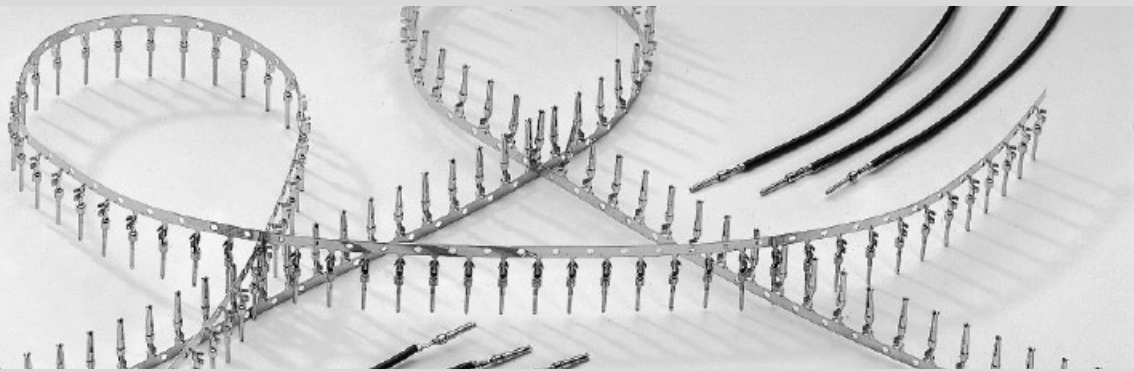

D-Sub - HD

| Identification | Wire gauge (mm ²) | Part No. | | | |
|--|------------------------------------|---|------------------|-------------------------|------------------|
| | | stamped male contacts | | stamped female contacts | |
| Performance levels Explanations see page 03.02 Other performance levels on request | | Performance level 3 | S4 ¹⁾ | Performance level 3 | S4 ¹⁾ |
| 500 pieces/box | AWG 26-24 0.14-0.22 stranded | 09 56 000 8177 | 09 56 000 8175 | 09 56 000 8277 | 09 56 000 8275 |
| 500 pieces/reel Unrolling left | | 09 56 000 8167 | 09 56 000 8165 | 09 56 000 8267 | 09 56 000 8265 |
| 10 000 pieces/reel Unrolling left | | 09 56 000 8157 | 09 56 000 8155 | 09 56 000 8257 | 09 56 000 8255 |
| Unrolling direction | | <p>500 pieces/reel Unrolling left 10 000 pieces/reel Unrolling left</p> <p>for HARTING tools</p> | | | |

¹⁾ S4 = 0.76 µm (30 µinch) Au or PdNi equivalent
Contact dimensions see page 03.05