


Number of contacts

15-78

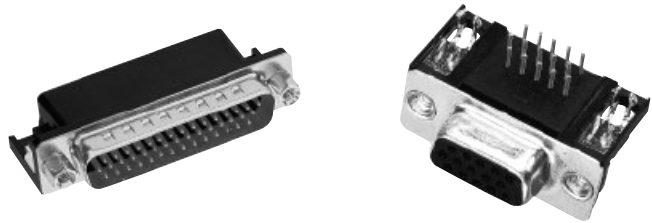

High density with stamped solder pins, angled with grounding board locks

D-Sub - HD

Identification	No. of contacts	Part No.			
Performance levels Explanations see page 03.02 Other performance levels on request		Performance level 3		S4 ¹⁾	
Male connector metal shell with dimples					
	15	09 56 162 781 .		09 56 162 581 .	
	26	09 56 262 781 .		09 56 262 581 .	
	44	09 56 362 781 .		09 56 362 581 .	
	62	09 56 462 781 .		09 56 462 581 .	
	78	09 56 562 781 .		09 56 562 581 .	
Female connector metal shell					
	15	09 56 152 761 .		09 56 152 561 .	
	26	09 56 252 761 .		09 56 252 561 .	
	44	09 56 352 761 .		09 56 352 561 .	
	62	09 56 452 761 .		09 56 452 561 .	
	78	09 56 552 761 .		09 56 552 561 .	
Please insert digit for flange thread or fitted female screw locks					
4-40 UNC ▶ 2					
fitted screw locks 4-40 UNC ▶ 3					

¹⁾ S4 = 0.76 µm (30 µinch) Au or PdNi equivalent