


Number of contacts

24

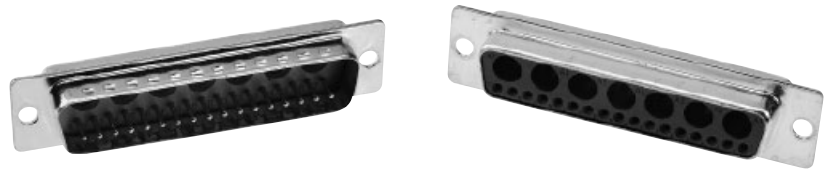





Mixed shells with pre-mounted signal solder cup contacts

Identification	No. of contacts ¹⁾	male connectors		female connectors	
		Performance level 3	S4 ²⁾	Performance level 3	S4 ²⁾
24W7		09 69 511 7247	09 69 511 5247	09 69 501 7247	09 69 501 5247

D-Sub - M







 Male connectors

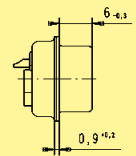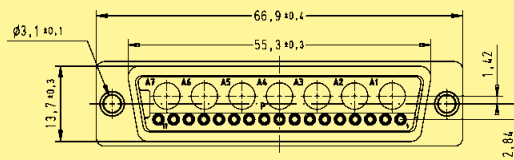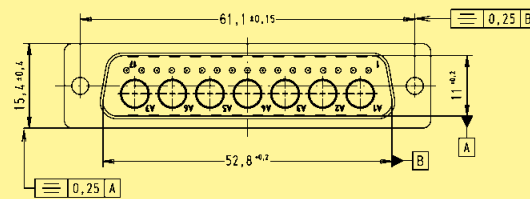

Solder cup termination for AWG 20 (0.5 mm²)

 Female connectors

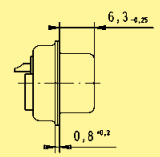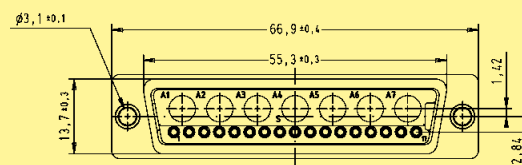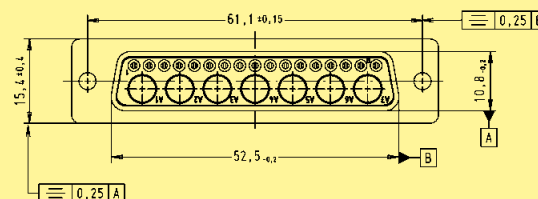

Solder cup termination for AWG 20 (0.5 mm²)

¹⁾ Explanations see page 04.03
²⁾ S4 = 0.76 µm Au or PdNi equivalent
 Board drillings see pages 04.30 ff

Order special contacts separately. See pages 04.21 ff