


High voltage contacts for cable applications

Identification	Wire gauge (mm ²)	Part No.	
Straight versions		Male contacts Plating: 1.3 µm Au ¹⁾	Female contacts Plating: 1.3 µm Au ¹⁾
	with solder termination	AWG 24 - 20 0.25 - 0.56	09 69 281 2550
with crimp termination ²⁾	AWG 30 - 24 0.05 - 0.25	09 69 282 2550	09 69 182 2550
Right angled versions			
with solder termination	AWG 24 - 20 0.25 - 0.56	09 69 681 2550	09 69 581 2550

D-Sub - M

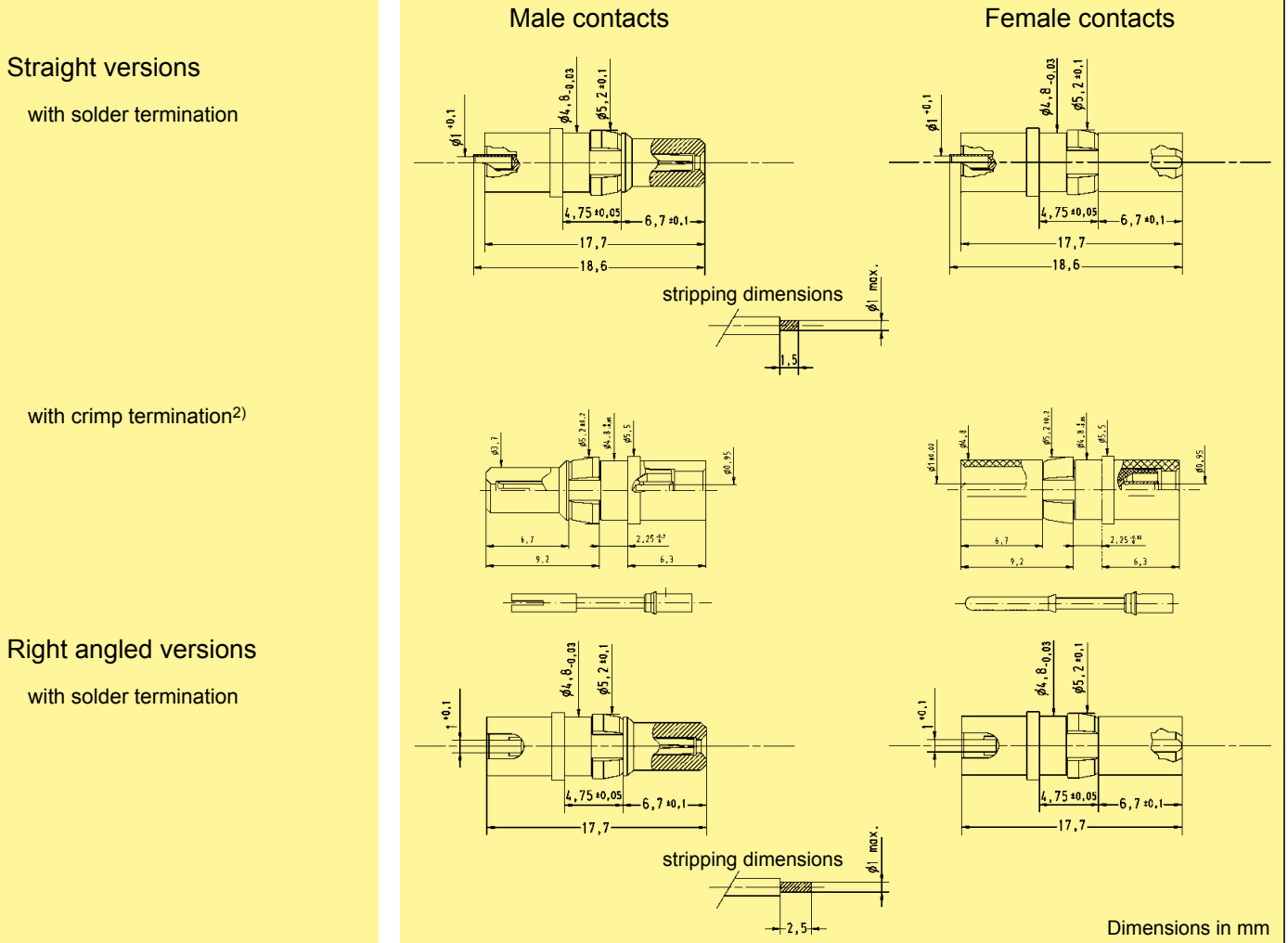

¹⁾ for mating and terminating side
²⁾ Tooling see chapter 31