


Number of contacts

**9-50**

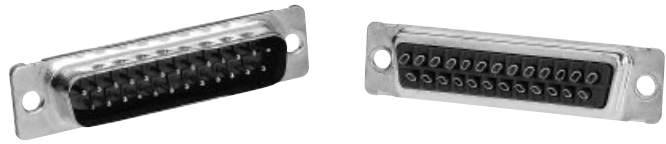

IP 67, turned solder cups

Identification	No. of contacts	Part No.
S4 <sup>1)</sup>		
Male connector metal shell with dimples	9 15 25 37 50	09 67 409 5615 09 67 415 5615 09 67 425 5615 09 67 437 5615 09 67 450 5615
Female connector metal shell	9 15 25 37 50	09 67 409 4715 09 67 415 4715 09 67 425 4715 09 67 437 4715 09 67 450 4715

D-Sub - W

<sup>1)</sup> S4 = 0.76 µm (30 µinch) Au or PdNi equivalent