


Number of contacts

# 9-25

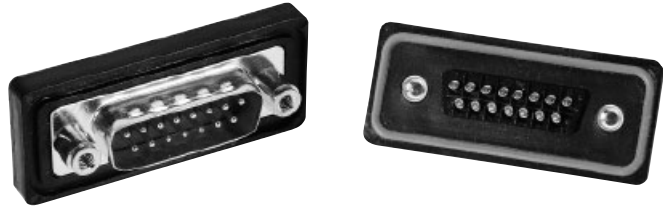

IP 67, turned solder cups, with front plastic mounting plate

Identification	No. of contacts	Part No.	
		S4 <sup>1)</sup>	
Male connector metal shell with dimples	9 15 25	09 67 709 .	615
		09 67 715 .	615
		09 67 725 .	615
Please insert digit for flange thread			
4-40 UNC ▶	7		
M3 ▶	9		
Female connector metal shell	9 15 25	09 67 709 .	715
		09 67 715 .	715
		09 67 725 .	715
Please insert digit for flange thread			
4-40 UNC ▶	6		
M3 ▶	8		

D-Sub - W

<sup>1)</sup> S4 = 0.76 µm (30 µinch) Au or PdNi equivalent