




## Top entry hoods with knurled or locking screws

Identification      No. of contacts      Part No.      Drawing      Dimensions in mm

**Hood<sup>3)</sup>**  
 Black thermoplastic with short locking screws

9	09 67 009 0442
15	09 67 015 0442
25	09 67 025 0442
37	09 67 037 0442
50	09 67 050 0442

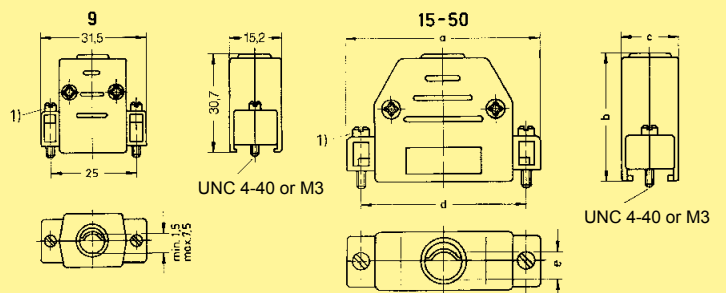

**Hood<sup>3)</sup>**  
 Metallized thermoplastic with short locking screws

9	09 67 009 04	3
15	09 67 015 04	3
25	09 67 025 04	3
37	09 67 037 04	3
50	09 67 050 04	3


Please insert digit for screw option

Thread 4-40 UNC	▶ 4
Thread M3	▶ 2

	a	b	c	d	e	
					min.	max.
15	40.0	34.7	15.2	33.3	3.3	8.5
25	53.2	39.7	15.2	47.0	3.5	11.0
37	70.0	39.7	15.2	63.5	3.5	11.0
50	67.5	39.7	18.2	61.1	9.3	12.0

**Knurled screw**  
 for metallized hood  
 Thread UNC  
 Thread M3


9-50	09 67 000 9925 <sup>2)</sup>
9-50	09 67 000 9930 <sup>2)</sup>

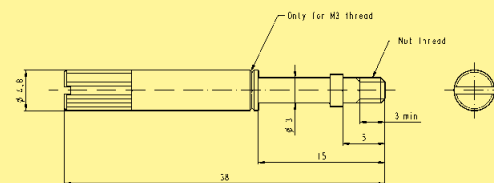

**Screened hood**  
 Order cover and internal metal screen separately

**Cover<sup>4)</sup>**  
 Black thermoplastic with knurled screws


9	09 67 009 0422
15	09 67 015 0422
25	09 67 025 0422
37	09 67 037 0422

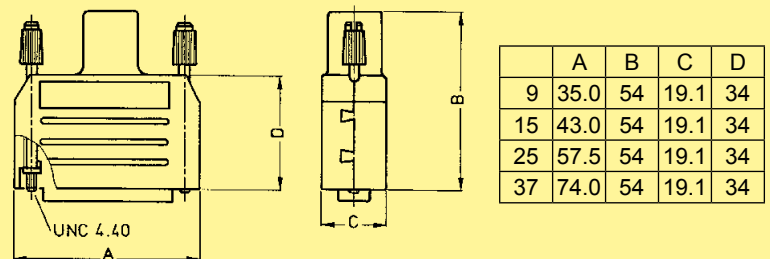

**Internal metal screen<sup>4)</sup>**  
 metallized

9	09 67 009 0421
15	09 67 015 0421
25	09 67 025 0421
37	09 67 037 0421

(Crimp tool see chapter 31)

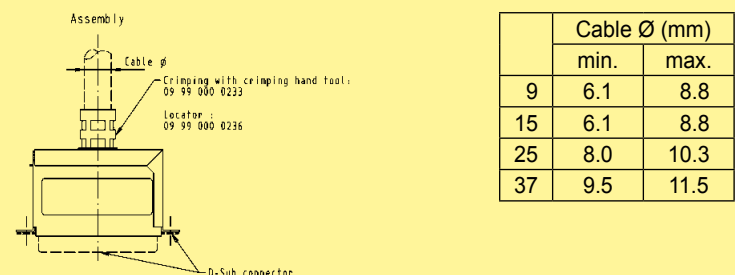

1) Use of knurled screws is possible. Please order separately  
 2) Order 2 for each hood  
 3) Operating temperature: -20 °C ... +90 °C  
 4) Operating temperature: -55 °C ... +110 °C