 
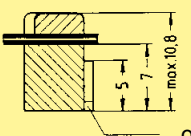
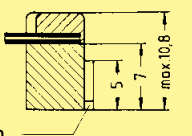
 


Number of contacts

6-64


 


Female connector

Identification	No. of contacts	Part No.		Drawing	Dimensions in mm	
Female connector with central polarization without strain relief clamp 		open end cover	closed end cover	open end cover	closed end cover	
						
	6	09 18 506 □ 803	09 18 506 □ 804			
	10	09 18 510 □ 803	09 18 510 □ 804			
	14	09 18 514 □ 803	09 18 514 □ 804			
	16	09 18 516 □ 803	09 18 516 □ 804			
	20	09 18 520 □ 803	09 18 520 □ 804			
	24	09 18 524 □ 803	09 18 524 □ 804			
	26	09 18 526 □ 803	09 18 526 □ 804			
	30	09 18 530 □ 803	09 18 530 □ 804			
	34	09 18 534 □ 803	09 18 534 □ 804			
	40	09 18 540 □ 803	09 18 540 □ 804			
	50	09 18 550 □ 803	09 18 550 □ 804			
	60	09 18 560 □ 803	09 18 560 □ 804			
	64	09 18 564 □ 803	09 18 564 □ 804			
	without strain relief clamp with bulk packaging 2) Packaging unit (PU) 5,000 pieces 3) PU 3,000 pieces	6	09 18 506 □ 803 58U ²⁾			
		10	09 18 510 □ 803 58U ²⁾			
		14	09 18 514 □ 803 58U ²⁾			
		16	09 18 516 □ 803 58U ²⁾			
		20	09 18 520 □ 803 58U ²⁾			
26		09 18 526 □ 803 58U ²⁾				
30		09 18 530 □ 803 58U ²⁾				
40		09 18 540 □ 803 58U ³⁾				
with strain relief clamp 	6	09 18 506 □ 813	09 18 506 □ 814*			
	10	09 18 510 □ 813	09 18 510 □ 814*			
	14	09 18 514 □ 813	09 18 514 □ 814*			
	16	09 18 516 □ 813	09 18 516 □ 814*			
	20	09 18 520 □ 813	09 18 520 □ 814*			
	24	09 18 524 □ 813				
	26	09 18 526 □ 813	09 18 526 □ 814*			
	30	09 18 530 □ 813	09 18 530 □ 814*			
	34	09 18 534 □ 813	09 18 534 □ 814*			
	40	09 18 540 □ 813	09 18 540 □ 814*			
	50	09 18 550 □ 813	09 18 550 □ 814*			
	60	09 18 560 □ 813	09 18 560 □ 814*			
	64	09 18 564 □ 813	09 18 564 □ 814*			
	with strain relief clamp with bulk packaging 3) Packaging unit (PU) 3,000 pieces 4) PU 2,500 pieces 5) PU 2,000 pieces 6) PU 1,500 pieces 7) PU 1,000 pieces	6	09 18 506 □ 813 58U ³⁾			
		10	09 18 510 □ 813 58U ³⁾			
		14	09 18 514 □ 813 58U ⁴⁾			
16		09 18 516 □ 813 58U ⁴⁾				
20		09 18 520 □ 813 58U ⁵⁾				
26		09 18 526 □ 813 58U ⁶⁾				
30		09 18 530 □ 813 58U ⁵⁾				
40		09 18 540 □ 813 58U ⁷⁾				

No. of contacts	6	10	14	16	20
A	12.20	17.30	22.40	24.90	30.00
B	5.08	10.16	15.24	17.78	22.86
No. of contacts	24	26	30	34	40
A	35.18	37.60	42.70	47.80	55.40
B	27.94	30.48	35.56	40.64	48.26
No. of contacts	50	60	64		
A	68.10	80.80	85.90		
B	60.96	73.66	78.74		

1) Pitch tolerance: ± 0.1
 * Not normally kept in stock

For performance level 3 please specify digit 
 For performance level 2 please specify digit 
 S4 = 0.76 µm (30 µinch) Au or PdNi equivalent

