


Number of contacts




4-64

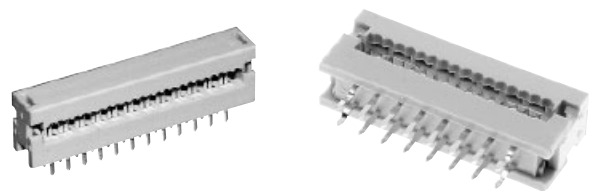

Pcb transition connector, 2 rows, low-profile with 5.5 mm height

Identification	No. of contacts	Part No.	Drawing	Dimensions in mm																																																
Pcb transition connector ²⁾ 2 rows Standard low-profile version	4	09 18 104 9622	<table border="1"> <thead> <tr> <th>No. of contacts</th> <th>A±0.38</th> <th>B±0.10</th> </tr> </thead> <tbody> <tr><td>4</td><td>10.38</td><td>2.54 x 1 = 2.54</td></tr> <tr><td>6</td><td>12.92</td><td>2.54 x 2 = 5.08</td></tr> <tr><td>8</td><td>15.46</td><td>2.54 x 3 = 7.62</td></tr> <tr><td>10</td><td>18.00</td><td>2.54 x 4 = 10.16</td></tr> <tr><td>14</td><td>23.08</td><td>2.54 x 6 = 15.24</td></tr> <tr><td>16</td><td>25.62</td><td>2.54 x 7 = 17.78</td></tr> <tr><td>20</td><td>30.74</td><td>2.54 x 9 = 22.86</td></tr> <tr><td>24</td><td>35.78</td><td>2.54 x 11 = 27.94</td></tr> <tr><td>26</td><td>38.32</td><td>2.54 x 12 = 30.48</td></tr> <tr><td>30</td><td>43.40</td><td>2.54 x 14 = 35.56</td></tr> <tr><td>34</td><td>48.48</td><td>2.54 x 16 = 40.64</td></tr> <tr><td>40</td><td>56.10</td><td>2.54 x 19 = 48.26</td></tr> <tr><td>50</td><td>68.80</td><td>2.54 x 24 = 60.96</td></tr> <tr><td>60</td><td>81.50</td><td>2.54 x 29 = 73.66</td></tr> <tr><td>64</td><td>86.58</td><td>2.54 x 31 = 78.74</td></tr> </tbody> </table>	No. of contacts	A±0.38	B±0.10	4	10.38	2.54 x 1 = 2.54	6	12.92	2.54 x 2 = 5.08	8	15.46	2.54 x 3 = 7.62	10	18.00	2.54 x 4 = 10.16	14	23.08	2.54 x 6 = 15.24	16	25.62	2.54 x 7 = 17.78	20	30.74	2.54 x 9 = 22.86	24	35.78	2.54 x 11 = 27.94	26	38.32	2.54 x 12 = 30.48	30	43.40	2.54 x 14 = 35.56	34	48.48	2.54 x 16 = 40.64	40	56.10	2.54 x 19 = 48.26	50	68.80	2.54 x 24 = 60.96	60	81.50	2.54 x 29 = 73.66	64	86.58	2.54 x 31 = 78.74	
	No. of contacts	A±0.38		B±0.10																																																
	4	10.38		2.54 x 1 = 2.54																																																
	6	12.92		2.54 x 2 = 5.08																																																
	8	15.46		2.54 x 3 = 7.62																																																
	10	18.00		2.54 x 4 = 10.16																																																
	14	23.08		2.54 x 6 = 15.24																																																
	16	25.62		2.54 x 7 = 17.78																																																
	20	30.74		2.54 x 9 = 22.86																																																
	24	35.78		2.54 x 11 = 27.94																																																
	26	38.32		2.54 x 12 = 30.48																																																
	30	43.40		2.54 x 14 = 35.56																																																
	34	48.48		2.54 x 16 = 40.64																																																
	40	56.10		2.54 x 19 = 48.26																																																
	50	68.80		2.54 x 24 = 60.96																																																
	60	81.50		2.54 x 29 = 73.66																																																
64	86.58	2.54 x 31 = 78.74																																																		
6	09 18 106 9622																																																			
8	09 18 108 9622																																																			
10	09 18 110 9622																																																			
14	09 18 114 9622																																																			
16	09 18 116 9622																																																			
20	09 18 120 9622																																																			
24	09 18 124 9622																																																			
26	09 18 126 9622																																																			
30	09 18 130 9622																																																			
34	09 18 134 9622																																																			
40	09 18 140 9622																																																			
50	09 18 150 9622																																																			
60	09 18 160 9622																																																			
64	09 18 164 9622																																																			

Pcb transition connector ²⁾ 2 rows Kinked low-profile version 2 kinked pins at each extremity	4	09 18 104 9422
	6	09 18 106 9422
	8	09 18 108 9422
	10	09 18 110 9422
	14	09 18 114 9422
	16	09 18 116 9422
	20	09 18 120 9422
	24	09 18 124 9422
	26	09 18 126 9422
	30	09 18 130 9422
	34	09 18 134 9422
	40	09 18 140 9422
	50	09 18 150 9422
	60	09 18 160 9422
	64	09 18 164 9422

 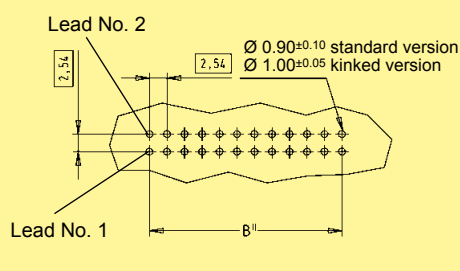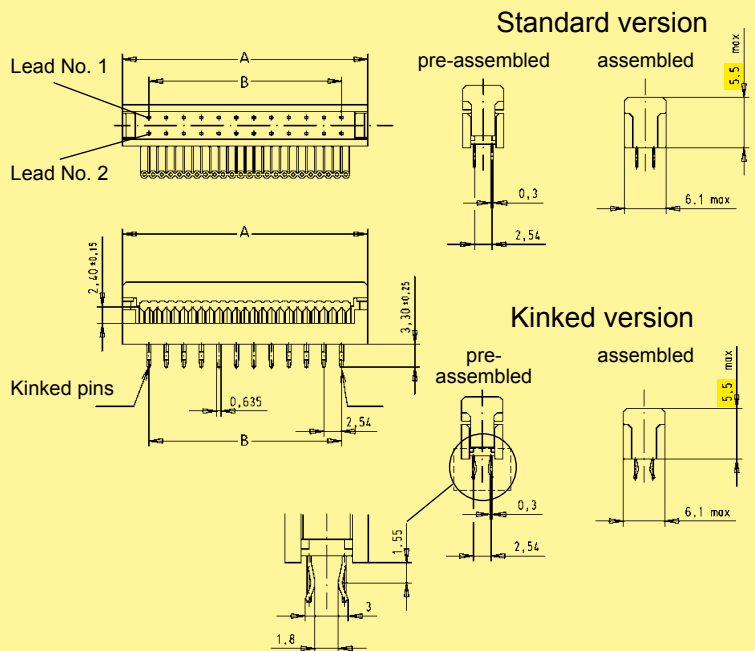

1) Pitch tolerance: ± 0.05
2) Not released for halogen free flat cables