
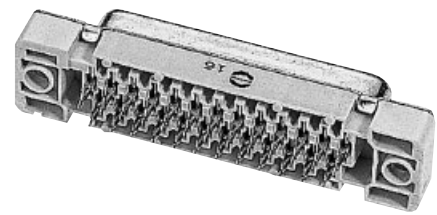


Number of contacts

9-50

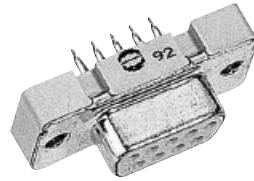

Press-in, straight without grounding press-in board locks

| Identification | No. of contacts | Part No. | |
|---|-----------------|-------------------------------|-------------------------------|
| Performance levels Explanations see page 20.08 Other performance levels on request | | Performance level 3 | Performance level 2 |
| Male connector Flange height x = 5.7 mm | | | |
| metal shell with dimples | 9 | 09 66 124 770 . | 09 66 124 670 . |
| | 15 | 09 66 224 770 . | 09 66 224 670 . |
| | 25 | 09 66 324 770 . | 09 66 324 670 . |
| Please insert digit for flange thread or fitted female screw locks | | | |
| ø 3.1 mm hole ▶ 4 ¹⁾ | | | |
| M3 ▶ 5 | | | |
| 4-40 UNC ▶ 6 | | | |
| fitted screw locks 4-40 UNC ▶ 7 ²⁾ | | | |
| Female connector Flange height x = 5.7 mm | | | |
| metal shell | 9 | 09 66 114 750 . | 09 66 114 650 . |
| | 15 | 09 66 214 750 . | 09 66 214 650 . |
| | 25 | 09 66 314 750 . | 09 66 314 650 . |
| | 37 | 09 66 414 750 . | 09 66 414 650 . |
| Please insert digit for flange thread or fitted female screw locks | | | |
| ø 3.1 mm hole ▶ 4 ¹⁾ | | | |
| M3 ▶ 5 | | | |
| 4-40 UNC ▶ 6 | | | |
| fitted screw locks 4-40 UNC ▶ 7 ²⁾ | | | |
| Female connector Flange height x = 6 mm | | | |
| metal shell | 9 | 09 66 114 750 . | 09 66 114 650 . |
| | 15 | 09 66 214 750 . | 09 66 214 650 . |
| | 25 | 09 66 314 750 . | 09 66 314 650 . |
| | 37 | 09 66 414 750 . | 09 66 414 650 . |
| | 50 | 09 66 514 750 . | 09 66 514 650 . |
| Please insert digit for flange thread or fitted female screw locks | | | |
| ø 3.1 mm hole ▶ 0 ¹⁾ | | | |
| M3 ▶ 1 | | | |
| 4-40 UNC ▶ 2 | | | |
| fitted screw locks 4-40 UNC ▶ 3 ²⁾ | | | |

Press-in technology

¹⁾ Not normally kept in stock
²⁾ Fitted screw locks 4-40 UNC not normally kept in stock for performance level 3
 Connector dimensions see page 20.13. Mating conditions see page 20.08.