


Number of contacts

9–37

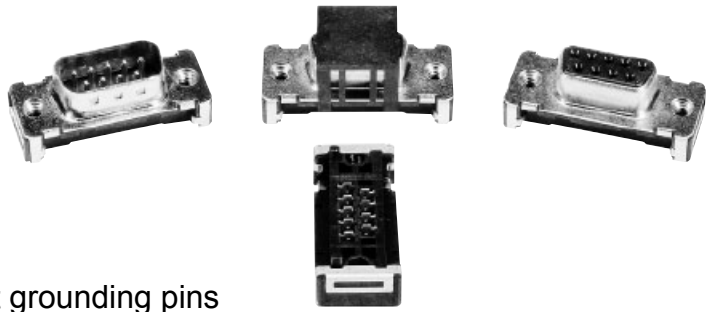

SMT stamped solder pins, straight without grounding pins

Identification	No. of contacts	Part No.	
Performance levels Explanations see page 21.02 Other performance levels on request		Performance level 3	
		Performance level 2	
Male connector metal shell with dimples			
	9	09 55 129 78 .. 741	09 55 129 68 .. 741
	15	09 55 229 78 .. 741	09 55 229 68 .. 741
	25	09 55 329 78 .. 741	09 55 329 68 .. 741
	37	09 55 429 78 .. 741	09 55 429 68 .. 741
Female connector metal shell			
	9	09 55 115 76 .. 741	09 55 115 66 .. 741
	15	09 55 215 76 .. 741	09 55 215 66 .. 741
	25	09 55 315 76 .. 741	09 55 315 66 .. 741
	37	09 55 415 76 .. 741	09 55 415 66 .. 741
Please insert digit for flange thread or fitted female screw locks			
	M3 ▶ 11		
	4-40 UNC ▶ 12		
	fixed screw locks M3 ▶ 21		
	fixed screw locks 4-40 UNC ▶ 22		

SMT
technology