


Number of contacts

9-37

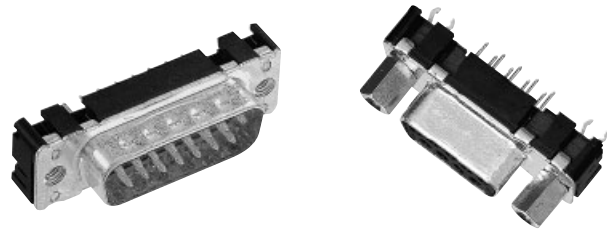

SMC stamped solder pins, straight with/without grounding board locks

Identification	No. of contacts	Part No.	
Performance levels Explanations see page 22.10 Other performance levels on request		Performance level 3	Performance level 2
Male connector metal shell with dimples			
Without grounding board locks	9 15 25 37	09 65 129 770 09 65 229 770 09 65 329 770 09 65 429 770	09 65 129 670 09 65 229 670 09 65 329 670 09 65 429 670
With grounding board locks	9 15 25 37	09 65 169 771 09 65 269 771 09 65 369 771 09 65 469 771	09 65 169 671 09 65 269 671 09 65 369 671 09 65 469 671
Female connector metal shell			
Without grounding board locks	9 15 25 37	09 66 115 750 09 66 215 750 09 66 315 750 09 66 415 750	09 66 115 650 09 66 215 650 09 66 315 650 09 66 415 650
With grounding board locks	9 15 25 37	09 66 155 751 09 66 255 751 09 66 355 751 09 66 455 751	09 66 155 651 09 66 255 651 09 66 355 651 09 66 455 651
Please insert digit for flange thread or fitted female screw locks			
M3 ▶ 1 4-40 UNC ▶ 2 fitted screw locks 4-40 UNC ▶ 3 ¹⁾			

SMC technology

¹⁾ Fitted screw locks 4-40 UNC not normally kept in stock for performance level 3
 Connector dimensions see page 22.13. Mating conditions see page 22.10.