
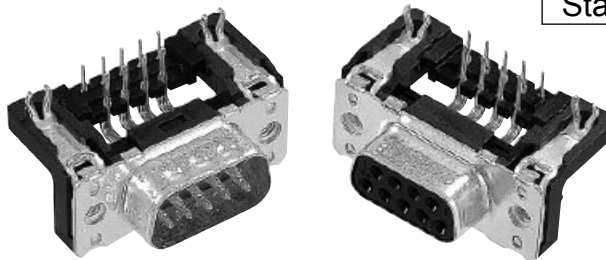


Standard Versions

Number of contacts

Mounting height

9-37

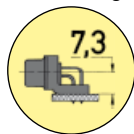

SMC stamped solder pins, angled with grounding board locks

Identification	No. of contacts	Part No.	
Performance levels Explanations see page 22.10 Other performance levels on request		Performance level 3	
		Performance level 2	
Male connector metal shell with dimples		2.84 mm pitch	
	9	09 65 167 781 . 1)	09 65 167 681 . 1)
	15	09 65 267 781 . 1)	09 65 267 681 . 1)
	25	09 65 367 781 . 1)	09 65 367 681 . 1)
	37	09 65 467 781 . 1)	09 65 467 681 . 1)
		2.54 mm pitch	
	9	09 65 166 781 .	09 65 166 681 .
	15	09 65 266 781 .	09 65 266 681 .
	25	09 65 366 781 .	09 65 366 681 .
	37	09 65 466 781 .	09 65 466 681 .
Female connector metal shell		2.84 mm pitch	
	9	09 66 157 761 . 1)	09 66 157 661 . 1)
	15	09 66 257 761 . 1)	09 66 257 661 . 1)
	25	09 66 357 761 . 1)	09 66 357 661 . 1)
	37	09 66 457 761 . 1)	09 66 457 661 . 1)
		2.54 mm pitch	
	9	09 66 156 761 .	09 66 156 661 .
	15	09 66 256 761 .	09 66 256 661 .
	25	09 66 356 761 .	09 66 356 661 .
	37	09 66 456 761 .	09 66 456 661 .
Please insert digit for flange thread or fitted female screw locks			
Ø 3.1 mm hole ▶ 0 ¹⁾			
M3 ▶ 1			
4-40 UNC ▶ 2			
fitted screw locks 4-40 UNC ▶ 3			

SMC technology

¹⁾ Not normally kept in stock