


Number of contacts

6-64

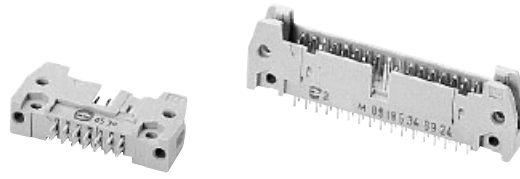

SMC male header with straight solder pins

Identification	No. of contacts	Part No.					
		Without levers		With short levers		With long levers	
SMC male header with straight solder pins Length: 2.9 mm	6	09 19 506	└ 924	09 19 506	└ 914	09 19 506	└ 904
	10	09 19 510	└ 924	09 19 510	└ 914	09 19 510	└ 904
	14	09 19 514	└ 924	09 19 514	└ 914	09 19 514	└ 904
	16	09 19 516	└ 924	09 19 516	└ 914	09 19 516	└ 904
	20	09 19 520	└ 924	09 19 520	└ 914	09 19 520	└ 904
	24	09 19 524	└ 924	09 19 524	└ 914	09 19 524	└ 904
	26	09 19 526	└ 924	09 19 526	└ 914	09 19 526	└ 904
	30	09 19 530	└ 924	09 19 530	└ 914	09 19 530	└ 904
	34	09 19 534	└ 924	09 19 534	└ 914	09 19 534	└ 904
	40	09 19 540	└ 924	09 19 540	└ 914	09 19 540	└ 904
	50	09 19 550	└ 924	09 19 550	└ 914	09 19 550	└ 904
	60	09 19 560	└ 924	09 19 560	└ 914	09 19 560	└ 904
	64	09 19 564	└ 924	09 19 564	└ 914	09 19 564	└ 904

SMC technology

22-24

* Not normally kept in stock
 For accessories see page 22.30
 For dimensions see page 22.23

For performance level 3 please specify digit 7*
 For performance level 2 please specify digit 6*
 S4 = 0.76 µm (30 µinch) Au or PdNi equivalent

