


Number of contacts


14-68

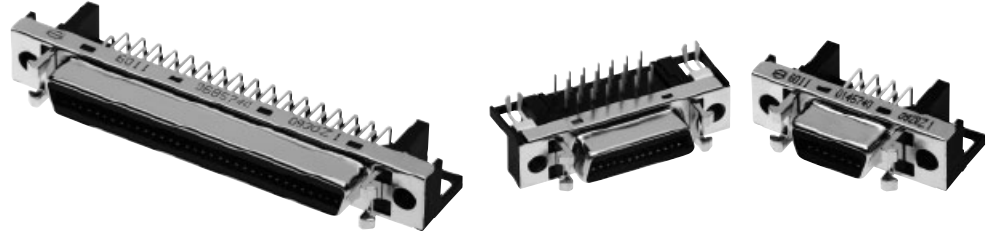

SMC female connectors, angled


| Identification | No. of contacts | for one reel (300 pieces) | | Part No. | standard tray packaging |
|---|-----------------|---------------------------|--------|--------------|-------------------------|
| SMC female connectors with angled solder pins | 14 | 60 11 014 57 | .. 710 | 60 11 014 57 | .. |
| | 20 | 60 11 020 57 | .. 710 | 60 11 020 57 | .. |
| | 26 | 60 11 026 57 | .. 710 | 60 11 026 57 | .. |
| | 36 | 60 11 036 57 | .. 710 | 60 11 036 57 | .. |
| | 50 | 60 11 050 57 | .. 710 | 60 11 050 57 | .. |
| | 68 | 60 11 068 57 | .. 710 | 60 11 068 57 | .. |
| Without board lock | 32 | | | | |
| With board lock | 40 | | | | |

Dimensions

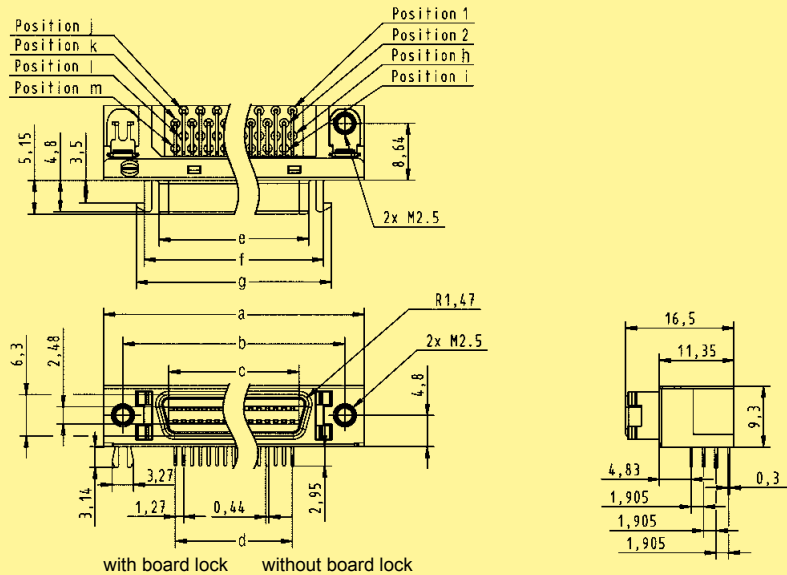


| | a | b | c | d | e | f | g | h | i | j | k | l | m | n |
|----|-------|-------|-------|-------|-------|-------|-------|----|----|----|----|----|----|------|
| 14 | 29.54 | 23.64 | 9.62 | 7.62 | 12.62 | 17.14 | 19.54 | 8 | 9 | 7 | 6 | 14 | 13 | 44.0 |
| 20 | 33.35 | 27.45 | 13.43 | 11.43 | 16.43 | 20.95 | 23.35 | 11 | 12 | 9 | 10 | 19 | 20 | 56.5 |
| 26 | 37.16 | 31.26 | 17.24 | 15.24 | 20.24 | 24.76 | 27.16 | 14 | 15 | 13 | 12 | 26 | 25 | 56.0 |
| 36 | 43.51 | 37.61 | 23.59 | 21.59 | 26.59 | 31.11 | 33.51 | 19 | 20 | 17 | 18 | 35 | 36 | 56.0 |
| 50 | 52.40 | 46.50 | 32.48 | 30.48 | 35.48 | 40.00 | 42.40 | 26 | 27 | 25 | 24 | 50 | 49 | 72.5 |
| 68 | 63.83 | 57.93 | 43.91 | 41.91 | 46.91 | 51.43 | 53.83 | 35 | 36 | 33 | 34 | 67 | 68 | 88.5 |

Board drillings
(Components side)

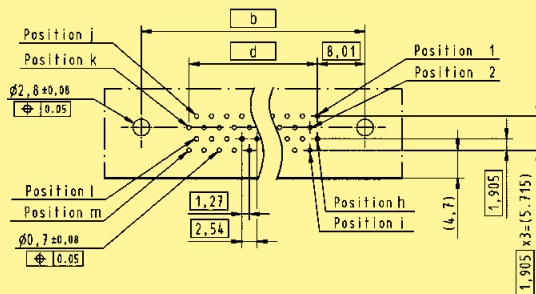

Packaging
(1 reel = 300 pieces)
Reel diameter = 380 mm

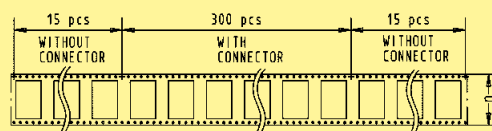

Dimensions in mm